


# Product data sheet

Specifications

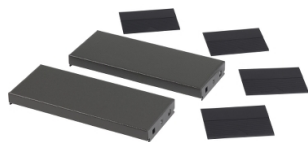

Side panels for the plinth, PanelSeT SFN, Spacial SF, Spacial SM, for electrical enclosure D400mm, set of 2, H100mm

NSYSPS4100

## Main

Range	Spacial
Accessory / Separate Part Categor	Enclosure accessory
Product Or Component Type	Plinth side panel
Application	Multi-purpose
Nominal Dimensions Of The Housing	-
Device Composition	fixing elements 4 corner cover 2 side panel
Range Compatibility	Spacial Spacial SF Spacial Spacial SM
Mounting Support	Front plinth

## Complementary

Fixing Mode	By screws
Colour	Grey (RAL 7022)
Surface Finish	Epoxy-polyester powder
Height	100 mm
Width	Nominal: 400 mm

## Environment

Ip Degree Of Protection	IP20 (complete plinth)
Ik Degree Of Protection	IK10

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	6.000 cm
Package 1 Width	11.500 cm
Package 1 Length	25.500 cm
Package 1 Weight	1.065 kg
Unit Type Of Package 2	S03
Number Of Units In Package 2	12
Package 2 Height	30.000 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 2 Width	30.000 cm
Package 2 Length	40.000 cm
Package 2 Weight	13.200 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	96
Package 3 Height	45.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	117.600 kg

## Contractual warranty

Warranty	18 months
----------	-----------

# Sustainability

**Green Premium™ label** is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency   RoHS/REACH

## Well-being performance

✓ Mercury Free

✓ Rohs Exemption Information   [Yes](#)

## Certifications & Standards

Reach Regulation	<a href="#">REACH Declaration</a>
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)
China Rohs Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations