


Product data sheet

Specifications

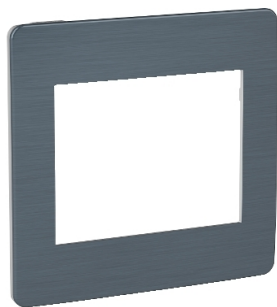

Orion - cover-frame 4X4 - 6 modules - aluminium / aluminium galaxy black

S733203719

⚠ Discontinued on: Jun 30, 2023

⚠ Discontinued

Main

Range	Orion
Aesthetic Name	Orion materials aluminium
Product Or Component Type	Cover frame

Complementary

Device Mounting	Flush
Number Of Gangs	1 gang
Number Of Modules	6 modules
Fixing Mode	Clip-in
Colour Tint	Gamma silver (RAL 9006) Aluminium galaxy black (Pantone Cool Gray 11C)
Surface Finish	Metallic
Surface Treatment	Metallic
Type Of Packing	Blister
Quantity Per Set	Set of 10
Ambient Air Temperature For Storage	-5...50 °C
Ambient Air Temperature For Operation	-5...35 °C
Material	Thermoplastic ABS-UV stabilised: decorative frame Metal
Height	120 mm
Width	127.5 mm
Depth	8.3 mm
Net Weight	0.031 kg

Environment

Ik Degree Of Protection	IK07
Ip Degree Of Protection	IP21D

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Environmental Characteristic	Hydrogen peroxide (H2O2)
	Oil
	Liquid soap
	Petrol
	Acetone
	UV resistant
	Alcohol
	Window-cleaning fluid
	Bleach

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	0.9 cm
Package 1 Width	15 cm
Package 1 Length	17 cm
Package 1 Weight	64 g
Unit Type Of Package 2	CAR
Number Of Units In Package 2	10
Package 2 Height	16 cm
Package 2 Width	15.2 cm
Package 2 Length	25.9 cm
Package 2 Weight	635 g

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

Eu Rohs Directive	Not applicable, out of EU RoHS legal scope
-------------------	--
