


Product data sheet

Specifications

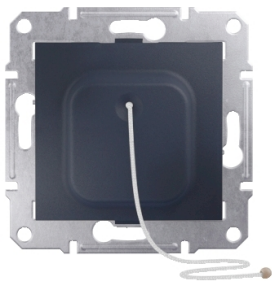

Sedna - 1pole pushbutton - 10A cord, graphite

SDN1200170

⚠ Discontinued on: Aug 31, 2018

⚠ Discontinued

Main

Range	Sedna
Product Or Component Type	Pull string switch
Device Presentation	Mechanism with fixing frame
Device Application	Control
Switch Function	1-pole push-button
Additionnal Feature	Cord operated
Colour Tint	Graphite

Complementary

Device Mounting	Flush
Surface Finish	Glossy
Marking	Without marking
Kind Of Terminals	Screwless terminals
Power Range	2300 W
Wire Structure	Rigid Flexible
Wire Stripping Length	13 mm
Fixing Mode	Claws, span of claws working range: 51...70 mm Screws
Height	71 mm
Width	71 mm
Depth	37 mm
Depth Of Visual Part	12 mm
Net Weight	0.07417 kg
Market Segment	Small commercial Residential

Environment

Ip Degree Of Protection	IP20
Conformity Mark	CE
Product Certifications	GOST-R
Standards	IEC 60669-1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	7.1 cm
Package 1 Width	4.2 cm
Package 1 Length	7.1 cm
Package 1 Weight	72 g