


Product data sheet

Specifications

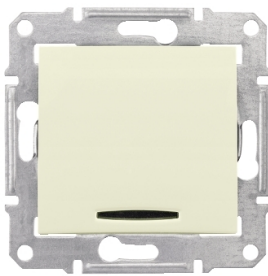

Sedna - 1pole pushbutton - 10A 12V~ label, locator light, beige

SDN1700447

⚠ Discontinued on: Mar 21, 2018

⚠ Discontinued

Main

Range	Sedna
Product Or Component Type	Push-button
Device Presentation	Mechanism with fixing frame
Device Application	Control
Switch Function	1-pole push-button
Additionnal Feature	With label holder
Colour Tint	Beige

Complementary

Device Mounting	Flush
Surface Finish	Glossy
Marking	Without marking
Kind Of Terminals	Screwless terminals
Power Range	120 W
Wire Structure	Rigid Flexible
Wire Stripping Length	12 mm
Fixing Mode	Claws, span of claws working range: 51...80 mm Screws
Height	71 mm
Width	71 mm
Depth	42 mm
Depth Of Visual Part	12 mm
Net Weight	0.07233 kg
Market Segment	Small commercial Residential

Environment

Ip Degree Of Protection	IP20
Conformity Mark	CE
Product Certifications	GOST-R
Standards	IEC 60669-1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	7.1 cm
Package 1 Width	7.1 cm
Package 1 Length	4.2 cm
Package 1 Weight	72.33 g

Contractual warranty

Warranty	18 months
----------	-----------