


# Product data sheet

Specifications

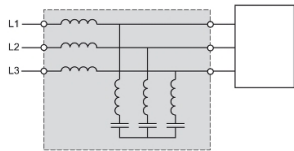

passive filter, Altivar, 19A, 400V, for variable speed drive

VW3A4603

 **End-of-service on:** Nov 24, 2021

 **Discontinued**

## Main

Product Or Component Type	Passive filter
Product Specific Application	Reduction of current harmonics

## Complementary

Range Compatibility	Altivar 71 Altivar 61
[Us] Rated Supply Voltage	400 V +/- 10 %
Power Supply Frequency	50 Hz +/- 5 %
Quantity Per Drive	1 filter per drive for ATV61HD11N4 1 filter per drive for ATV61HU75N4 1 filter per drive for ATV61WD11N4 1 filter per drive for ATV61WD11N4C 1 filter per drive for ATV61WU75N4 1 filter per drive for ATV61WU75N4C 1 filter per drive for ATV71HD11N4 1 filter per drive for ATV71HU75N4 1 filter per drive for ATV71PD11N4Z 1 filter per drive for ATV71PU75N4Z 1 filter per drive for ATV71WD11N4 1 filter per drive for ATV71WU75N4
[In] Rated Current	19 A
Network Number Of Phases	3 phases
Thdi	10 % for ATV61WD11N4 motor: 11 kW/15 hp 10 % for ATV61WD11N4C motor: 11 kW/15 hp 10 % for ATV61WU75N4 motor: 7.5 kW/10 hp 10 % for ATV61WU75N4C motor: 7.5 kW/10 hp 16 % for ATV61HD11N4 motor: 11 kW/15 hp 16 % for ATV61HU75N4 motor: 7.5 kW/10 hp 16 % for ATV71HD11N4 motor: 11 kW/15 hp 16 % for ATV71HU75N4 motor: 7.5 kW/10 hp 16 % for ATV71PD11N4Z motor: 11 kW/15 hp 16 % for ATV71PU75N4Z motor: 7.5 kW/10 hp 16 % for ATV71WD11N4 motor: 11 kW/15 hp 16 % for ATV71WU75N4 motor: 7.5 kW/10 hp
Max Current	1.5 x nominal current
Efficiency	98 %
Cos Phi	1 (150 % of line current) 0.85 (75 % of line current) 0.99 (100 % of line current)
Electrical Connection	terminal, connection capacity: 16 mm²
Electrical Insulation Class	Class F
Net Weight	21 kg

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

## Environment

Ip Degree Of Protection	IP20
Relative Humidity	5...85 % without condensation
Ambient Air Temperature For Operation	40...55 °C (with current derating 3 % per °C) 5...40 °C (without current derating)
Ambient Air Temperature For Storage	-25...55 °C
Operating Altitude	> 1000...4000 m with current derating 5 % per 1000 m

## Packing Units


Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

## Contractual warranty

Warranty	18 months
----------	-----------

Dimensions Drawings

Dimensions

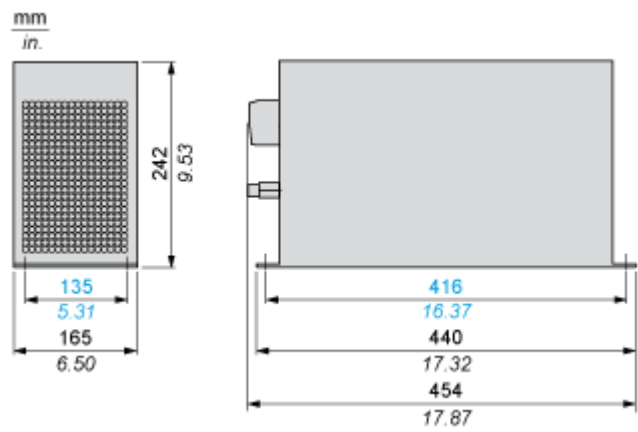

Mounting and Clearance

Mounting Recommendations

Vertical Mounting Only

