


Product data sheet

Specifications

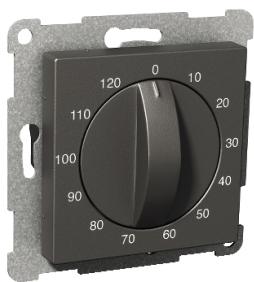

Exxact mechanical timer 0-120 minutes 2-pole anthracite

WDE003477

Main

Range	Exxact
Product Or Component Type	Timer
Quantity Per Set	1 piece

Complementary

Device Presentation	Mechanism with fixing frame
Device Mounting	Flush
Technology Type	Electromechanical
Switch Function	2-pole
Rated Current	16 A
Rated Voltage	250 V AC
Colour Tint	Anthracite
Time Delay Range	0...120 min
Connections - Terminals	Screw terminals
Clamping Connection Capacity	1 x 1.5...2 x 2.5 mm² for solid cable(s) 1 x 1.5...2 x 2.5 mm² for solid stranded cable(s)
Material	ABS (acrylonitrile butadiene-styrene)
Embedding Depth	32 mm
Height	71 mm
Width	71 mm
Projecting Depth	22 mm

Environment

Ip Degree Of Protection	IP20
Standards	EN 60669-1

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	7.6 cm
Package 1 Width	7.6 cm
Package 1 Length	9.6 cm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Weight	154.0 g
Unit Type Of Package 2	BB1
Number Of Units In Package 2	10
Package 2 Height	16.4 cm
Package 2 Width	16.8 cm
Package 2 Length	27.2 cm
Package 2 Weight	1.702 kg
Unit Type Of Package 3	CAR
Number Of Units In Package 3	20
Package 3 Height	19.0 cm
Package 3 Width	30.4 cm
Package 3 Length	39.8 cm
Package 3 Weight	3.772 kg

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

Certifications & Standards

Reach Regulation	REACH Declaration
Eu Rohs Directive	Compliant with Exemptions
China Rohs Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations