

Product data sheet

Specifications



pilot light Ø8 - IP40 - green -
protruding LED included - <= 30 mA
- faston

XVLA193

⚠ Discontinued on: Jan 29, 2021

⚠ Discontinued

Main

Range Of Product	Harmony XVL
Product Or Component Type	LED pilot light with black bezel
Component Name	XVL
Mounting Diameter	8 mm
Light Source	Protruding LED
Light Block Colour	Green
Protection Type	Without protection
Ip Degree Of Protection	IP40 conforming to IEC 60529 IP40 conforming to NF C 20-010

Complementary

Input Current	30 mA DC
Connections - Terminals	Tag for soldering connectors Tag for Faston connectors
[Ui] Rated Insulation Voltage	50 V conforming to IEC 60947-1
Bulb Lifespan	100000 h
Terminals Description Iso N°1	(X1-X2)PL
Height	10 mm
Width	10 mm
Depth	36 mm
Net Weight	0.003 kg

Environment

Product Certifications	CSA UL
Protective Treatment	TC
Ambient Air Temperature For Operation	-25...70 °C
Ambient Air Temperature For Storage	-40...70 °C
Overvoltage Category	Class 3 conforming to IEC 60536 Class 3 conforming to NF C 20-030

Packing Units

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	1.6 cm
Package 1 Width	1.6 cm
Package 1 Length	4 cm
Package 1 Weight	3 g


Contractual warranty

Warranty	18 months
----------	-----------

Dimensions Drawings

LED Pilot Light

Dimensions

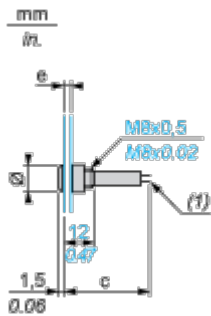

(1) Tags for Faston connectors or soldered connections


e panel thickness: 1 to 8 mm/0.03 to 0.31 in.

C		Ø	
mm	in.	mm	in.
32	1.26	12	0.47

Mounting and Clearance

LED Pilot Light

Panel Drilling

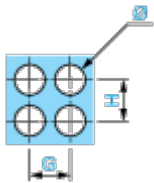

Ø min		G min		H min	
mm	in.	mm	in.	mm	in.
8.2	0.32	12.5	0.49	12.5	0.49