

# Product data sheet

Specifications



## Rotating beacon, 120 mm, red, without buzzer, 12 V AC DC

XVR12J04

⚠ Discontinued on: Mar 31, 2022

⚠ End-of-service on: May 11, 2022

⚠ Discontinued

### Main

Range Of Product	Harmony XVR
Product Or Component Type	Prewired rotating mirror beacon
Sound Signalling	Without
Device Short Name	XVR
Mounting Diameter	120 mm
Ip Degree Of Protection	IP23 conforming to IEC 60529
[Us] Rated Supply Voltage	12 V AC/DC
Light Source	High luminosity LED, red

### Complementary

Material	ABS (acrylonitrile butadiene-styrene): body part AS: globe
Cad Overall Width	120 mm
Cad Overall Depth	120 mm
Net Weight	0.5 kg
Marking	CE
Product Mounting	By 3 M5 screws
Supply Voltage Limits	10...15 V DC 10.8...13.2 V AC
[Uimp] Rated Impulse Withstand Voltage	0.8 kV
Current Consumption	250 mA
Flashing Frequency	2.3 Hz
Clamping Connection Capacity	0.83 mm²
Awg Gauge	AWG 18
Cable Length	400 mm

### Environment

Standards	EN 61000-6-2 EN 61000-6-4
Protective Treatment	TC
Ambient Air Temperature For Storage	-35...70 °C
Ambient Air Temperature For Operation	-10...50 °C

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

<b>Electrical Shock Protection Class</b>	Class II conforming to IEC 61140
--	----------------------------------

## Contractual warranty

Warranty	18 months
----------	-----------

## Sustainability

**Green Premium™** label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



Transparency   RoHS/REACH

## Well-being performance

✓ Toxic Heavy Metal Free

✓ Mercury Free

✓ Rohs Exemption Information   Yes


## Certifications & Standards

Reach Regulation	<a href="#">REACH Declaration</a>
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
China Rohs Regulation	<a href="#">China RoHS declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	<a href="#">End of Life Information</a>
California Proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>

Dimensions Drawings

Rotating Mirror Beacon

Dimensions

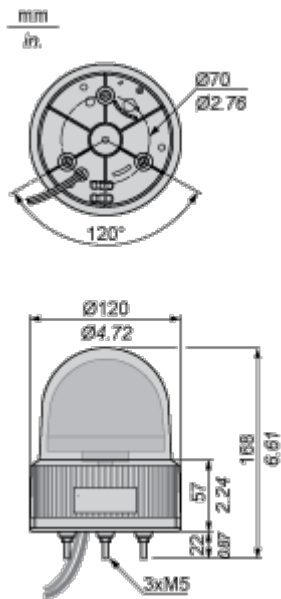

Mounting and Clearance

Rotating Mirror Beacon

Panel Cut-out

