

# Product data sheet

Specifications



## Pre wired connectors XZ, straight female, M12, 4 pins, cable PUR 5 m

XZCP1141L5

### Main

Range Of Product	Telemecanique Cabling components
Accessory / Separate Part Category	Cabling accessory
Accessory / Separate Part Type	Pre-wired connectors
Series Name	General purpose

### Complementary

Electrical Connection	Straight female connector M12, 4 pins
Cable Connector Fixing	Interlocked Screw-on
Collar Material	Metal
Status Led	Without
Cable Length	5 m
Cable Outer Diameter	5.2 mm
Cable Composition	4 x 0.34 mm <sup>2</sup>
Wire Insulation Material	PUR
[Ue] Rated Operational Voltage	250 V AC 300 V DC
[In] Rated Current	4 A
Contact Resistance	5000 µOhm
Minimum Insulating Resistance	1 GΩ
Net Weight	0.19 kg

### Environment

Ip Degree Of Protection	IP65 IP69K IP67
Product Certifications	cULus
Ambient Air Temperature For Operation	-40...80 °C static -5...80 °C flexing
Ambient Air Temperature For Storage	-40...80 °C

### Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 1 Height	3.0 cm
Package 1 Width	17.0 cm
Package 1 Length	17.0 cm
Package 1 Weight	154.0 g
Unit Type Of Package 2	S02
Number Of Units In Package 2	20
Package 2 Height	15.0 cm
Package 2 Width	30.0 cm
Package 2 Length	40.0 cm
Package 2 Weight	3.436 kg
Unit Type Of Package 3	P06
Number Of Units In Package 3	320
Package 3 Height	77.0 cm
Package 3 Width	80.0 cm
Package 3 Length	60.0 cm
Package 3 Weight	55.28 kg

## Contractual warranty

Warranty	18 months
----------	-----------

## Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)



RoHS/REACH

## Well-being performance

✓ Mercury Free

✓ Rohs Exemption Information [Yes](#)

## Certifications & Standards


Reach Regulation [REACH Declaration](#)

Eu Rohs Directive Pro-active compliance (Product out of EU RoHS legal scope)

California Proposition 65  
WARNING: This product can expose you to chemicals including: Diisononyl phthalate (DINP), which is known to the State of California to cause cancer, and Diisodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)

Dimensions Drawings

Dimensions

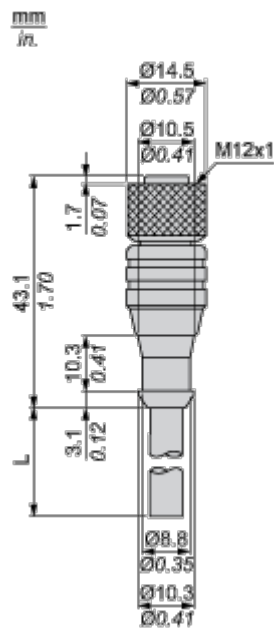


L : Lenght of cable

Connections and Schema

Connections and Schemes

---

Connector

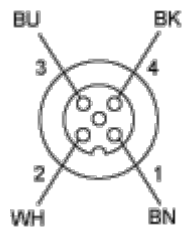

- BN : Brown
- BK : Black
- BU : Blue
- WH : White