


Product datasheet

Specifications

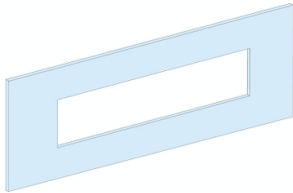

FRONT PLATE 3-15 EZC100 VERTICAL WIDTH 600/650 5M

03303

⚠ Discontinued on: 15 Jun 2023

⚠ Discontinued

Main

Range	Prisma
Range Of Product	Prisma G Prisma P
Product Or Component Type	Front plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G enclosure Prisma Prisma P cubicle
Type Of Front Plate	Cut-out
Installed Device	EasyPact: fixed EZC100 without earth leakage protection - control: toggle - vertical installation
Poles Description	15 x 1P: mounting plate support: EZC100 vertical installation 5 x 3P: mounting plate support: EZC100 vertical installation 3 x 4P: mounting plate support: EZC100 vertical installation
Operating Position	Vertical

Complementary

Enclosure/Cubicle Description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Cubicle - width 650 mm depth 400 mm
Connection Position	Direct connection
Number Of Vertical Modules [50 Mm]	5
Standards	IEC 61439-2 IEC 61439-1
Product Certifications	ASEFA
Material	Steel
Surface Finish	Smooth Matt
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	250 mm
Width	500 mm
Net Weight	0.86 kg
Quantity Per Set	Set of 1

Excluding VAT and subject to change. Please check with your local distributor through "Where to buy"

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Functional Unit	600 mm Prisma G floor-standing enclosure EasyPact EZC100 without fixed toggle vertical 1P 15 direct 5
	600 mm Prisma G wall-mounted enclosure EasyPact EZC100 without fixed toggle vertical 1P 15 direct 5
	600 mm Prisma G floor-standing enclosure EasyPact EZC100 without fixed toggle vertical 3P 5 direct 5
	600 mm Prisma G wall-mounted enclosure EasyPact EZC100 without fixed toggle vertical 3P 5 direct 5
	600 mm Prisma G floor-standing enclosure EasyPact EZC100 without fixed toggle vertical 4P 3 direct 5
	600 mm Prisma G wall-mounted enclosure EasyPact EZC100 without fixed toggle vertical 4P 3 direct 5
	650 mm 400 mm Prisma P cubicle EasyPact EZC100 without fixed toggle vertical 1P 15 direct 5
	650 mm 400 mm Prisma P cubicle EasyPact EZC100 without fixed toggle vertical 3P 5 direct 5
	650 mm 400 mm Prisma P cubicle EasyPact EZC100 without fixed toggle vertical 4P 3 direct 5

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	3.0 cm
Package 1 Width	26.0 cm
Package 1 Length	51.0 cm
Package 1 Weight	870.0 g
Unit Type Of Package 2	CAR
Number Of Units In Package 2	10
Package 2 Height	17.0 cm
Package 2 Width	27.0 cm
Package 2 Length	53.0 cm
Package 2 Weight	8.86 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	90
Package 3 Height	42.0 cm
Package 3 Width	80.0 cm
Package 3 Length	120.0 cm
Package 3 Weight	79.74 kg

Sustainability



Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile