


Product datasheet

Specifications

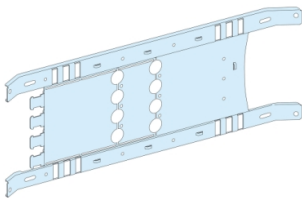

MOUNTING PLATE VIGI NSX/ CVS TOGGLE - 4P 250A HORIZONTAL WIDTH 650

03412

⚠ Discontinued on: 15 Jun 2023

⚠ Discontinued

Price: 2,257.45 ZAR

Main

Range	Prisma
Range Of Product	Prisma P
Product Or Component Type	Mounting plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma P cubicle
Installation Description	Cubicle - width 650 mm depth 400 mm
Installed Device	EasyPact: fixed CVS100...160 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS250 without earth leakage protection - control: toggle - horizontal installation ComPact: fixed INS250 - control: direct front rotary handle - horizontal installation ComPact: fixed INV250 - control: direct front rotary handle - horizontal installation ComPact: fixed NSX100...160 without earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX250 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS100...160 with earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS250 with earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX100...160 with earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX250 with earth leakage protection - control: toggle - horizontal installation
Poles Description	1 x 4P: fixed CVS100...160 horizontal installation 1 x 4P: fixed CVS250 horizontal installation 1 x 3P: fixed INS250 horizontal installation 1 x 4P: fixed INS250 horizontal installation 1 x 3P: fixed INV250 horizontal installation 1 x 4P: fixed INV250 horizontal installation 1 x 4P: fixed NSX100...160 horizontal installation 1 x 4P: fixed NSX250 horizontal installation
Number Of Vertical Modules [50 Mm]	4 module(s): CVS100...160 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): CVS250 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): INS250, direct in 650 mm Widecubicle 4 module(s): INV250, direct in 650 mm Widecubicle 4 module(s): NSX100...160 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): NSX250 without earth leakage protection , direct in 650 mm Widecubicle 4 module(s): CVS100...160 with earth leakage protection , direct in 650 mm Widecubicle 4 module(s): CVS250 with earth leakage protection , direct in 650 mm Widecubicle 4 module(s): NSX100...160 with earth leakage protection , direct in 650 mm Widecubicle 4 module(s): NSX250 with earth leakage protection , direct in 650 mm Widecubicle
Standards	IEC 61439-2

Excluding VAT and subject to change. Please check with your local distributor through "Where to buy"

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Product Certifications	ASEFA
------------------------	-------

Complementary

Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface Finish	Smooth Matt
Colour	White (RAL 9001)
Width	650 mm
Height	192 mm
Net Weight	1.48 kg
Functional Unit	650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 without fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle EasyPact CVS250 without fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INS250 fixed direct front rotary handle horizontal 3P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INS250 fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INV250 fixed direct front rotary handle horizontal 3P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact INV250 fixed direct front rotary handle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 with fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle EasyPact CVS250 with fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed toggle horizontal 4P 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle horizontal 4P 1 direct 4 12.5 mm

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	5.6 cm
Package 1 Width	19.5 cm
Package 1 Length	57.5 cm
Package 1 Weight	1.51 kg
Unit Type Of Package 2	CAR
Number Of Units In Package 2	5
Package 2 Height	22 cm
Package 2 Width	22.4 cm
Package 2 Length	61 cm
Package 2 Weight	7.65 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	100
Package 3 Height	105 cm
Package 3 Width	80 cm
Package 3 Length	120 cm

Package 3 Weight

165 kg

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information