


Product datasheet

Specifications

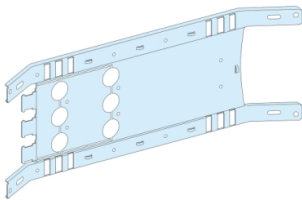

M.PL.3-4V.FIXED NS-INS250 TOG.

03420

! Discontinued on: 22 Jan 2022

! End-of-service on: 11 Jan 2023

! Discontinued

Price: 2,682.66 ZAR

Main

Range	Prisma
Range Of Product	Prisma P
Product Or Component Type	Mounting plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma P cubicle
Installation Description	Cubicle - width 650 mm depth 400 mm
Installed Device	EasyPact: fixed CVS100...160 without earth leakage protection - control: toggle - vertical installation EasyPact: fixed CVS250 without earth leakage protection - control: toggle - vertical installation ComPact: fixed INS250 - control: direct front rotary handle - vertical installation ComPact: fixed INV250 - control: direct front rotary handle - vertical installation ComPact: fixed NSX100...160 without earth leakage protection - control: toggle - vertical installation ComPact: fixed NSX250 without earth leakage protection - control: toggle - vertical installation EasyPact: fixed CVS100...160 with earth leakage protection - control: toggle - vertical installation EasyPact: fixed CVS250 with earth leakage protection - control: toggle - vertical installation ComPact: fixed NSX100...160 with earth leakage protection - control: toggle - vertical installation ComPact: fixed NSX250 with earth leakage protection - control: toggle - vertical installation

Poles Description	1 x 3P: fixed INS250 vertical installation 1 x 4P: fixed INS250 vertical installation 1 x 3P: fixed INV250 vertical installation 1 x 4P: fixed INV250 vertical installation 4 x 3P: fixed CVS100...160 vertical installation 3 x 4P: fixed CVS100...160 vertical installation 4 x 3P: fixed CVS250 vertical installation 3 x 4P: fixed CVS250 vertical installation 4 x 3P: fixed NSX100...160 vertical installation 3 x 4P: fixed NSX100...160 vertical installation 4 x 3P: fixed NSX250 vertical installation 3 x 4P: fixed NSX250 vertical installation 3 x 3P: fixed INS250 vertical installation 2 x 4P: fixed INS250 vertical installation 3 x 3P: fixed INV250 vertical installation 2 x 4P: fixed INV250 vertical installation
-------------------	--

Excluding VAT and subject to change. Please check with your local distributor through "Where to buy"

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Number Of Vertical Modules [50 Mm]	9 module(s): CVS100...160 without earth leakage protection , direct in 650 mm Widecubicle 9 module(s): CVS250 without earth leakage protection , direct in 650 mm Widecubicle 7 module(s): INS250, Linergy FC in 650 mm Widecubicle 9 module(s): INS250, direct in 650 mm Widecubicle 7 module(s): INV250, Linergy FC in 650 mm Widecubicle 9 module(s): INV250, direct in 650 mm Widecubicle 6 module(s): NSX100...160 without earth leakage protection , Linergy FC in 650 mm Widecubicle 8 module(s): NSX100...160 without earth leakage protection , direct in 650 mm Widecubicle 7 module(s): NSX250 without earth leakage protection , Linergy FC in 650 mm Widecubicle 9 module(s): NSX250 without earth leakage protection , direct in 650 mm Widecubicle 11 module(s): CVS100...160 with earth leakage protection , direct in 650 mm Widecubicle 11 module(s): CVS250 with earth leakage protection , direct in 650 mm Widecubicle 8 module(s): NSX100...160 with earth leakage protection , Linergy FC in 650 mm Widecubicle 10 module(s): NSX100...160 with earth leakage protection , direct in 650 mm Widecubicle 9 module(s): NSX250 with earth leakage protection , Linergy FC in 650 mm Widecubicle 11 module(s): NSX250 with earth leakage protection , direct in 650 mm Widecubicle
Standards	IEC 61439-2
Product Certifications	ASEFA

Complementary

Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface Finish	Matt Smooth
Colour	White
Width	593 mm
Height	152 mm
Depth	136 mm
Net Weight	1.28 kg

Functional Unit	650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 without fixed toggle vertical 3P 4 direct 9 162.5 mm
	650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 without fixed toggle vertical 4P 3 direct 9 162.5 mm
	650 mm 400 mm Prisma P cubicle EasyPact CVS250 without fixed toggle vertical 3P 4 direct 9 162.5 mm
	650 mm 400 mm Prisma P cubicle EasyPact CVS250 without fixed toggle vertical 4P 3 direct 9 162.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INS250 fixed direct front rotary handle vertical 3P 1 Linergy FC 7 112.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INS250 fixed direct front rotary handle vertical 3P 3 Linergy FC 7 112.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INS250 fixed direct front rotary handle vertical 4P 1 Linergy FC 7 112.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INS250 fixed direct front rotary handle vertical 4P 2 Linergy FC 7 112.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INS250 fixed direct front rotary handle vertical 3P 1 direct 9 212.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INS250 fixed direct front rotary handle vertical 4P 1 direct 9 212.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INS250 fixed direct front rotary handle vertical 3P 3 direct 9 212.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INS250 fixed direct front rotary handle vertical 4P 2 direct 9 212.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INV250 fixed direct front rotary handle vertical 3P 1 Linergy FC 7 112.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INV250 fixed direct front rotary handle vertical 3P 3 Linergy FC 7 112.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INV250 fixed direct front rotary handle vertical 4P 1 Linergy FC 7 112.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INV250 fixed direct front rotary handle vertical 4P 2 Linergy FC 7 112.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INV250 fixed direct front rotary handle vertical 3P 1 direct 9 212.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INV250 fixed direct front rotary handle vertical 4P 1 direct 9 212.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INV250 fixed direct front rotary handle vertical 3P 3 direct 9 212.5 mm
	650 mm 400 mm Prisma P cubicle ComPact INV250 fixed direct front rotary handle vertical 4P 2 direct 9 212.5 mm
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed toggle vertical 3P 4 Linergy FC 6 62.5 mm
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed toggle vertical 4P 3 Linergy FC 6 62.5 mm
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed toggle vertical 3P 4 direct 8 162.5 mm
	650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed toggle vertical 4P 3 direct 8 162.5 mm
	650 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed toggle vertical 3P 4 Linergy FC 7 62.5 mm
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle vertical 3P 4 direct 11 162.5 mm
	650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle vertical 4P 3 direct 11 162.5 mm

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	6.2 cm
Package 1 Width	15.3 cm
Package 1 Length	59.1 cm
Package 1 Weight	1.534 kg
Unit Type Of Package 2	BB1
Number Of Units In Package 2	5
Package 2 Height	20.5 cm
Package 2 Width	33.0 cm
Package 2 Length	61.5 cm

Package 2 Weight	8.2 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	80
Package 3 Height	83.0 cm
Package 3 Width	80.0 cm
Package 3 Length	120.0 cm
Package 3 Weight	143.2 kg

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information