


Product datasheet

Specifications

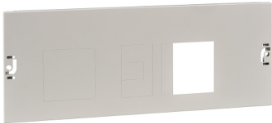

FRONT PLATE VIGI NSX.TOGGLE / CVS.ROTARY - 4P 250A HORIZONTAL WIDTH650 4MODULES

03606

! Discontinued

! Discontinued on: 15 Jun 2023

Price: 702.90 ZAR

Main

Range	Prisma
Range Of Product	Prisma P
Product Or Component Type	Front plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma P cubicle
Type Of Front Plate	Cut-out

Excluding VAT and subject to change. Please check with your local distributor through "Where to buy"

Installed Device	EasyPact: fixed CVS100...160 without earth leakage protection - control: direct front rotary handle - horizontal installation EasyPact: fixed CVS250 without earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX100...160 without earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX100...160 without earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX250 without earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX250 without earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX100...160 without earth leakage protection - control: motor mechanism - horizontal installation ComPact: fixed NSX250 without earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX100...160 without earth leakage protection - control: toggle - horizontal installation ComPact: plug-in NSX250 without earth leakage protection - control: toggle - horizontal installation EasyPact: fixed CVS100...160 with earth leakage protection - control: direct front rotary handle - horizontal installation EasyPact: fixed CVS250 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX100...160 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX100...160 with earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX250 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: fixed NSX250 with earth leakage protection - control: toggle - horizontal installation ComPact: plug-in NSX100...160 without earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: plug-in NSX100...160 without earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX250 without earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: plug-in NSX250 without earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX100...160 with earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX100...160 with earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX100...160 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: plug-in NSX100...160 with earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX250 with earth leakage protection - control: toggle - horizontal installation ComPact: fixed NSX250 with earth leakage protection - control: motor mechanism - horizontal installation ComPact: plug-in NSX250 with earth leakage protection - control: direct front rotary handle - horizontal installation ComPact: plug-in NSX250 with earth leakage protection - control: motor mechanism - horizontal installation Enerlin'X: fixed FDM121 - control: remote control - vertical installation
Poles Description	1 x 4P: mounting plate support: CVS100...160 horizontal installation 1 x 4P: mounting plate support: CVS250 horizontal installation 1 x 4P: mounting plate support: NSX100...160 horizontal installation 1 x 4P: mounting plate support: NSX250 horizontal installation
Operating Position	Horizontal
Complementary	
Enclosure/Cubicle Description	Cubicle - width 650 mm depth 400 mm
Connection Position	Direct connection
Number Of Vertical Modules [50 Mm]	4
Standards	IEC 61439-1 IEC 61439-2
Product Certifications	ASEFA

Surface Finish	Smooth Matt
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	200 mm
Net Weight	0.76 kg
Quantity Per Set	Set of 1
Functional Unit	650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 without fixed direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle EasyPact CVS250 without fixed direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed toggle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without fixed motor mechanism horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in motor mechanism horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 without plug-in toggle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed toggle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 without fixed motor mechanism horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in motor mechanism horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 without plug-in toggle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle EasyPact CVS100...160 with fixed direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle EasyPact CVS250 with fixed direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed toggle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with fixed motor mechanism horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in motor mechanism horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX100...160 with plug-in toggle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed toggle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 with fixed motor mechanism horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in direct front rotary handle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in motor mechanism horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle ComPact NSX250 with plug-in toggle horizontal 4P 1 direct 4 650 mm 400 mm Prisma P cubicle Enerlin'X FDM121 fixed remote control vertical 1

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	4.000 cm

Package 1 Width	21.000 cm
Package 1 Length	52.000 cm
Package 1 Weight	780.000 g
Unit Type Of Package 2	CAR
Number Of Units In Package 2	10
Package 2 Height	16.500 cm
Package 2 Width	22.000 cm
Package 2 Length	53.000 cm
Package 2 Weight	8.300 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	360
Package 3 Height	102.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	373.640 kg

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information